

# POWERS™

## Emergency Tempering Valve Cross Reference

Powers to Powers

### HydroGuard®

Bronze Finish	ASSE Listed	Inlet	Outlet	Flow at 30psid
ES150RB	No	1/2"	1/2"	14 gpm
ES200RB	No	3/4"	1"	36
ES400RB	No	1 1/4"	1 1/2"	66

Chrome Finish	ASSE Listed	Inlet	Outlet	Flow at 30psid
ES150RC	No	1/2"	1/2"	14 gpm
ES200PC	No	3/4"	1"	36
ES400PC	No	1 1/4"	1 1/2"	66



ISO 9001-2000  
CERTIFIED



USA: Phone: 1.800.669.5430 • Fax 1.847.229.0526 • www.powerscontrols.com  
Canada: Phone: 1.888.208.8927 • Fax 1.888.479.2887 • www.powerscontrols.ca

S-P-ETV-X-Reference 0917


### HydroGuard XP® - ASSE 1071 Listed



WITH Temp. Gauge	LESS Temp. Gauge	ASSE Listed	Inlet	Outlet	Flow at 30psid	Bypass Flow at 30psid
ES150-11	ES150-1	Yes	1/2"	1/2"	8.7 gpm	6.5 gpm
ETV200-13	ETV200-1	Yes	3/4"	1"	32.9 gpm	30.0 gpm
ETV400-15	ETV400-1	Yes	1 1/4"	1 1/2"	83.2 gpm	50.0 gpm
ETV500-17	ETV500-1	Yes	2"	2"	119.4 gpm	81.0 gpm



WITH Temp. Gauge	LESS Temp. Gauge	ASSE Listed	Inlet	Outlet	Flow at 30psid	Bypass Flow at 30psid
ES150-22	ES150-2	Yes	1/2"	1/2"	8.7 gpm	6.5 gpm
ETV200-24	ETV200-2	Yes	3/4"	1"	32.9 gpm	30.0 gpm
ETV400-26	ETV400-2	Yes	1 1/4"	1 1/2"	83.2 gpm	50.0 gpm
ETV500-28	ETV500-2	Yes	2"	2"	119.4 gpm	81.0 gpm

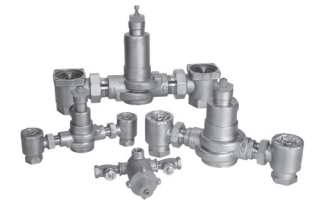

# POWERS™

A Watts Water Technologies Company

© 2009 Powers