 




# User Manual

# WiFi Thermostat 562

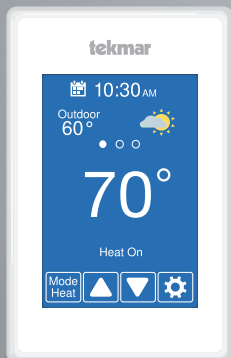

**⚠ WARNING**

 Please read carefully before proceeding with installation. Your failure to follow any attached instructions or operating parameters may lead to the product's failure. Keep this Manual for future reference.

**THINK SAFETY FIRST**

**tekmar**<sup>®</sup>  
A **WATTS** Brand

# Home Screen

After 60 seconds of inactivity, the thermostat home screen displays only the time and the temperature.

The diagram illustrates the tekmar thermostat home screen and its various sub-menus. The main screen displays the current time (10:30 AM), outdoor temperature (60°), and floor temperature (70°). It also shows the current equipment operation (Heat On) and a schedule event (Early Start). The screen includes navigation icons for going to the schedule, adjusting temperatures, and accessing settings.

**Home Screen Elements:**

- Go to schedule:** Arrow pointing to the calendar icon.
- Current time:** Arrow pointing to the 10:30 AM display.
- Swipe to view:** Arrow pointing to the weather and temperature indicators.
- Current temperature:** Arrow pointing to the 70° floor temperature display.
- Equipment operation (Heat or Cool On):** Arrow pointing to the Heat On status.
- Go to settings:** Arrow pointing to the gear icon.

**Change operating mode:** This sub-menu allows users to select the thermostat's operating mode:

- Heat
- Cool
- Auto Heat-Cool (highlighted in yellow)
- Off

**Touch ▲ or ▼ to adjust temperatures:** This sub-menu allows users to adjust the thermostat's temperature settings:

- Heat To: 70
- Cool To: 75
- Hold Until 5:00 PM (highlighted in yellow)
- Save to Schedule

**'Save to schedule' applies the new temperature to the current schedule event.** This sub-menu allows users to save the current temperature to the schedule:

- Save to Schedule


**MENU SELECTION:** This sub-menu provides access to various thermostat settings:

- AWAY
- SCHEDULE
- DISPLAY
- TIME
- WIFI
- SETUP
- FAN
- WIFI: Connected

# User Settings



## Away

Use the Away setting to save energy when the building is unoccupied

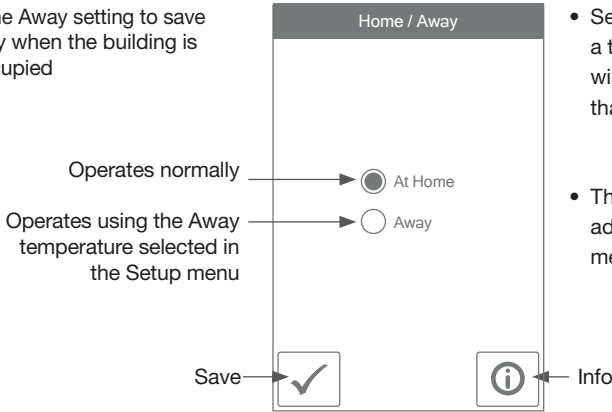

- Selecting the Away setting on a thermostat or the mobile app will affect all devices linked to that location through the app.
- The Away temperature can be adjusted in the Setup / Temps menu.

## Schedule

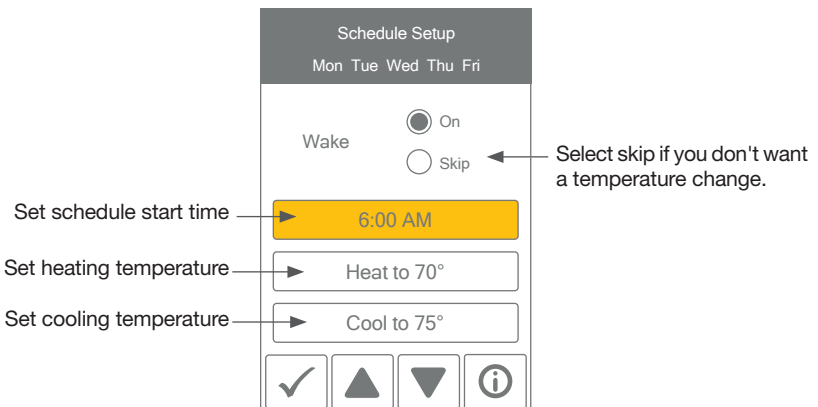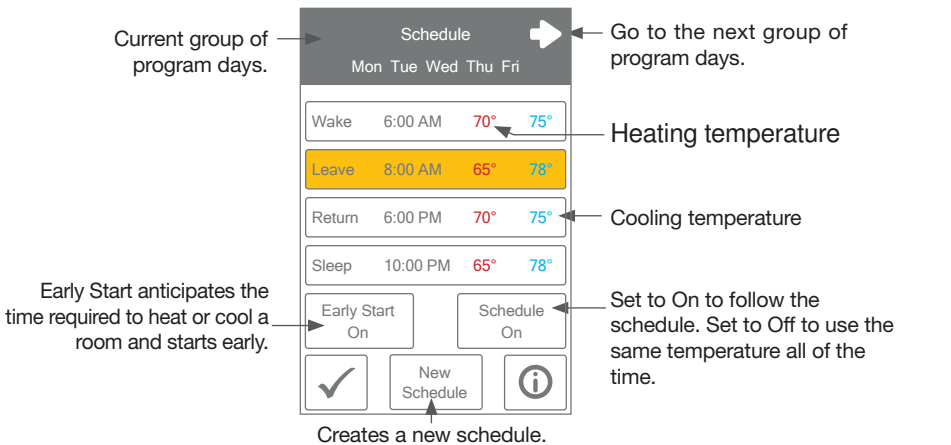

# Display

DISPLAY 1/2

Temperature Units: °F

Energy Use: Monthly

Brightness - Active: 80%

Brightness - Inactive: 50%

Theme: Light

Language: English

← ▲ ▼

Select °F or °C

Brightness when touching the display

Choose the background color

Energy use. See below.

Brightness after 60 second timeout of no use

Select English, French or Spanish

10 second count down to allow the screen to be cleaned with a moist cloth.

DISPLAY OPTIONS 2/2

Clean Screen: OFF

← ▲ ▼

## Energy Use

Daily Usage


Today	0 hrs	0 hrs
Yesterday	0 hrs	0 hrs
Tue	0 hrs	0 hrs
Mon	0 hrs	0 hrs
Sun	0 hrs	0 hrs
Sat	0 hrs	0 hrs
Fri	0 hrs	0 hrs

Monthly Usage

View each day's run time for both heating and cooling.

Toggle between Daily and Monthly Usage.

# Time

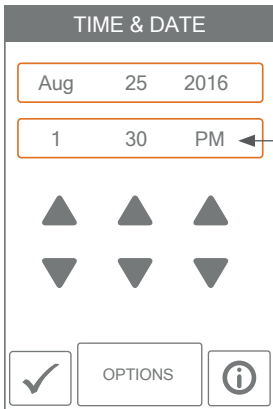

When connected to the Internet, the time can be set automatically.

The time and date can be manually set by highlighting a field and then using the ▲ or ▼ buttons.

Time options are:

- 12 hour or 24 hour time format
- Automatic or manual time setting
- Time zone
- Daylight savings time

## NOTICE


Incorrectly setting the time and date manually may prevent the thermostat from communicating to the mobile app. Automatic time source is recommended when using an Internet connection.

# Fan



The fan is normally off when set to auto but turns on when needed for the heating or cooling equipment.

When a programmable schedule is used, there is a fan setting for each time period.

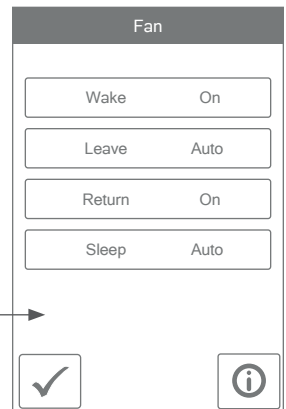


# WiFi

## NOTICE

Before using the WiFi features of this product, you must accept the Terms of Use, as amended from time to time and available at [Watts.com/terms-of-use](https://www.watts.com/terms-of-use). If you do not accept these terms, this product can still be used without WiFi features.

The thermostat includes a step by step tutorial to setup the WiFi connection.

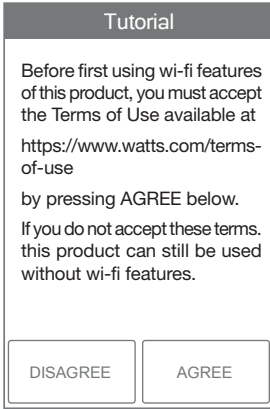


**Tutorial**

Before first using wi-fi features of this product, you must accept the Terms of Use available at <https://www.watts.com/terms-of-use> by pressing AGREE below. If you do not accept these terms, this product can still be used without wi-fi features.

DISAGREE    AGREE

### Step 1

Agree to Terms of Use

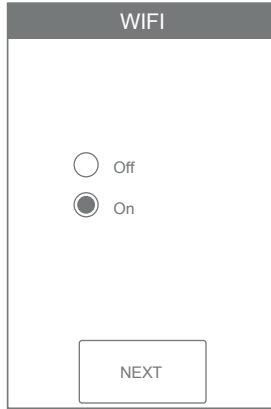


**WiFi**

Off  
 On

NEXT

### Step 2

Turn on WiFi

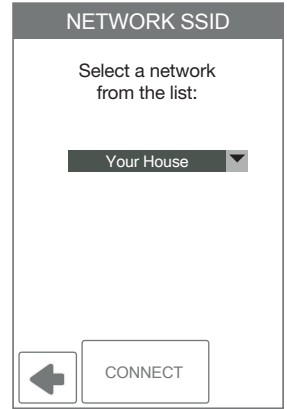

**NETWORK SSID**


Select a network from the list:

Your House ▼

←    CONNECT

### Step 3

Enter wireless network name. It must support WPA2 security encryption.

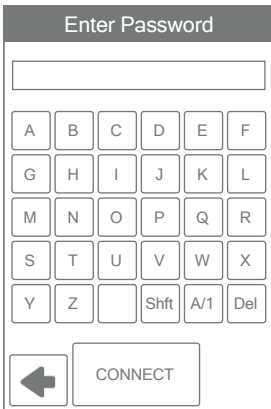

**Enter Password**


[Empty input field]

A B C D E F  
G H I J K L  
M N O P Q R  
S T U V W X  
Y Z [Space] Shft A/1 Del

←    CONNECT

### Step 4

Enter WiFi password.

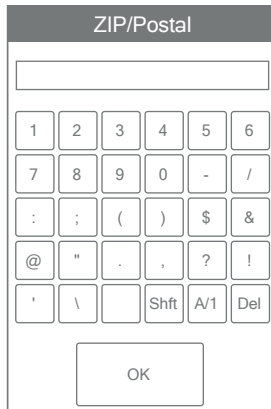

**ZIP/Postal**


[Empty input field]

1 2 3 4 5 6  
7 8 9 0 - /  
: ; ( ) \$ &  
@ " ' , ? !  
' \ [Space] Shft A/1 Del

OK

### Step 5

Enter ZIP or postal code. This determines your location for weather information.

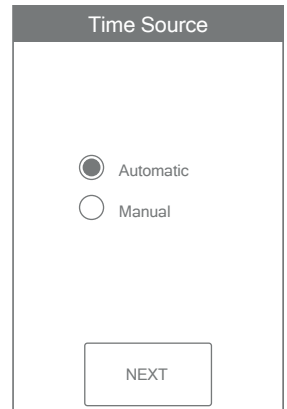

**Time Source**

Automatic  
 Manual

NEXT

### Step 6

Select if the time is set automatically from the Internet or manually.



**Need help? Go to our website or contact us.**

[tekmarControls.com](https://tekmarControls.com) | [tekmar.customerservice@wattswater.com](mailto:tekmar.customerservice@wattswater.com) | 1-800-438-3903

**tekmar**<sup>®</sup>

**A WATTS Brand**

All specifications are subject to change without notice.

Tel: 1-800-438-3903 • Fax: (250) 984-0815  
[tekmarControls.com](https://tekmarControls.com)